


Roof/wall mounting


Wall mounting

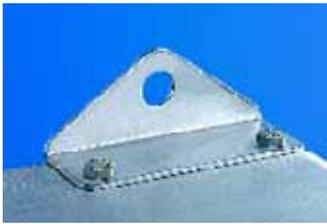

Wall angle

For compact enclosures (additional holes required in the enclosure).

Material	Colour	Packs of	Model No. SZ
Sheet steel	RAL 7035	1	2505.500
Stainless steel 1.4301 (AISI 304)	-	1	2583.000

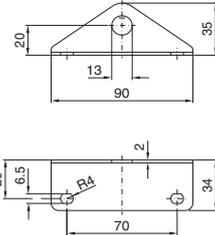

Wall bracket

For wall attachment of TS and ES enclosures at the roof, e. g. with heavy components on the door or built-in swing frame.

Material:
Sheet steel, zinc-plated, passivated

Packs of	Model No. PS
4	4595.000

Possible alternative:

With TS 8 inside the enclosure (without mounting plate), buying bracket TS 8800.470, see page 931.



Wall mounting bracket for CS wall-mounted enclosures

For mounting on a wall or panel.

Material:
Stainless steel 1.4301 (AISI 304)

Packs of	Model No. CS
4	9765.120



Pole clamp

For reliable, convenient fastening to round or square poles.

For pole diameter/size:
 Ø from 40 to 190 mm
 □ from 50 to 150 mm

Material:
 Mounting angles, clamping section:
 Sheet steel, zinc-plated, passivated
 Clamping strap: Stainless steel 1.4301 (AISI 304)

Wall mounting



For KL, EB, BG, AE, KS

Supply includes:
 2 mounting angles, 600 mm long,
 4 clamping sections,
 2 clamping straps,
 4 clamping brackets,
 4 screws and nuts M8
 for attachment to the enclosure.

Packs of	Model No. SZ
1 set	2584.000



For CS wall-mounted enclosures

Supply includes:
 4 clamping sections,
 2 clamping straps,
 4 clamping brackets.

Packs of	Model No. CS
1 set	9765.125

B
7.5