

Interior installation

Mounting plates

Mounting plate attachment

For additional clamping and to reduce potential vibration of the mounting plate. Select according to mounting position, installation type and enclosure.

Material:

- Sheet steel

Surface finish:

- Zinc-plated

Supply includes:

- Assembly parts



For TS, SE

Installation options:

- Side, at half height in conjunction with mounting plate infill
- In the penultimate position
- Set forward (supplied state)

Benefit:

No impairment to the mounting surface, but mounting is only possible from the enclosure rear

Packs of	Model No.
10 pc(s).	8800.630

+ Accessories:

- Mounting plate infill, see page 591



For TS, SE

Installation options:

- Side
- Rear, flush with enclosure frame

Benefit:

No impairment to the mounting surface, but mounting is only possible from the enclosure rear

Packs of	Model No.
10 pc(s).	8800.610



For TS, SE

Installation options:

- Side
- Rear, flush with enclosure frame
- Set forward on a 25 mm pitch pattern


Benefit:

No impairment to the mounting surface, for optional use as attachment or screw-fastening

Packs of	Model No.
10 pc(s).	8800.090

! Also required:

- Punched section with mounting flange 17 x 73 mm for the inner mounting level, see page 606 (for Fig. 3)

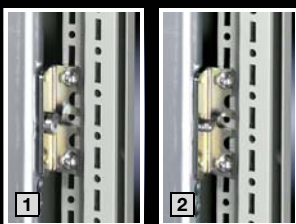

1 Mounting plate attached in the rearmost installation position

2 Mounting plate screw-fastened from the rear in the rearmost installation position

3 Mounting plate in a set forward position, either attached or screw-fastened (not shown)



For TS, SE

Installation options:

- Side
- Rear, flush with enclosure frame

Slide over the plate at the side and secure with screws. Additionally, the mounting plate may be drilled and screw-fastened at the rear C-edge.

Packs of	Model No.
10 pc(s).	8800.050