

Keyboards, supports and drawers

TFT holder

Suitable for mounting TFTs using VESA 75/100 adaptor up to 21" on

- Attachment CP 40, 6501.070, see page 139
- Attachment CP 60, for support arm connection
 - 120 x 65 mm, 6206.360, see page 147
- Vertical support arm via tilting adaptor +100°/-60°, 6206.460, see page 147

Material:

- Sheet steel

Surface finish:

- Spray-finished

Colour:

- RAL 7024

Dimensions mm	Packs of	Model No.
477 x 372 x 110.5	1 pc(s).	2383.030

Technical details:

Available on the Internet



Keyboard, pull-out

with integral trackball

Super-slimline keyboard with cursor keys and trackball. The handle also serves as a hand rest. The 10° angled pullout ensures ergonomic working.

For installation in:

- Any sufficiently large surface (e.g. door, side panel)
- Front panels
- Directly in a Comfort-Panel and Optipanel of a suitable size, selectable via configurators at www.rittal.com

Technical specifications:

Keyboard:

- 84 short-stroke keys, IBM-AT compatible (MF2), including cursor keys
- With integral 16 mm trackball
- Interface: 2 x USB
- Operating temperature: +5°C...+50°C
- Storage temperature: -10°C...+60°C
- Humidity: max. 95 % (non-condensing)

Keyboard layout	Packs of	Model No.
German	1 pc(s).	6002.130

Material:

- Sheet steel

Surface finish:



 
- Front panel: Powder-coated

Colour:

- RAL 7035

Protection category IP to IEC 60 529:

- IP 65 (at the front, sealed)

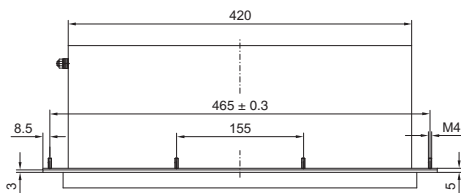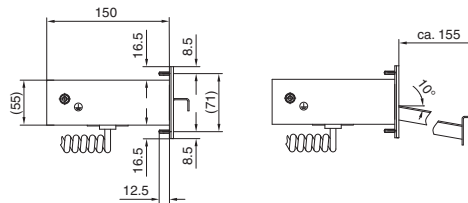

Mounting cut-out

