


ISV distribution enclosures

Mounting kits

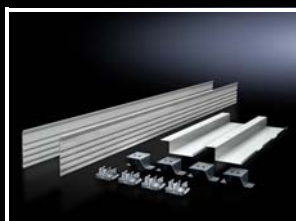

Mounting kits

for TS, SE

For mounting installation modules in TS/SE enclosures.

Note:


- TS 8 baying systems, see from page 68
- System enclosures SE 8, see from page 81

Supply includes:

- Mounting aid support
- Contact hazard protection
- Support for contact hazard protection
- Basic supports for frame holders
- Assembly parts

For enclosure	Packs of							Page
Design: Sheet steel, spray finished Model No.		8604.500	8606.500	9666.955	9666.915	9666.965	9666.925	8684.500 8685.500 8686.500 5830.500
Design: Stainless steel 1.4301 Model No.		-	8452.600	-	-	-	-	8457.600 5851.500
Enclosure width mm		600		850		1100		600
Enclosure height mm		2000			2000			1800
Enclosure depth mm		400	600	400	600	400	600	400 500 600
Width unit (WU)		2		3		4		2
Height unit (U)		12		12		12		11
Model No.	1 pc(s).	9666.900		9666.910		9666.920		9666.930
Also required								
Mounting angle 11 U	2 pc(s).	-	-	-	-	-	-	9666.711 305
Mounting angle 12 U	2 pc(s).	9666.712	-	9666.712	-	9666.712	-	- 305
Depth stay for enclosure depth 400/500/600 mm	2 pc(s).	-	-	-	-	9666.730	-	- 305
Accessories								
Cross rail 2 WU	2 pc(s).	9666.722	-	9666.722	-	9666.722	-	9666.722 305
Cross rail 3 WU	2 pc(s).	-	-	9666.723	-	9666.723	-	- 305
Cross rail 4 WU	2 pc(s).	-	-	-	-	9666.724	-	- 305
Mounting angle 2 U	2 pc(s).	9666.702	-	9666.702	-	9666.702	-	9666.702 305
Mounting angle 3 U	2 pc(s).	9666.703	-	9666.703	-	9666.703	-	9666.703 305
Mounting angle 4 U	2 pc(s).	9666.704	-	9666.704	-	9666.704	-	9666.704 305
Mounting angle 5 U	2 pc(s).	-	-	-	-	-	-	9666.705 305
Mounting angle 6 U	2 pc(s).	-	-	-	-	-	-	9666.706 305
Mounting angle 7 U	2 pc(s).	-	-	-	-	-	-	9666.707 305
Depth stay for enclosure depth 400/500/600 mm	2 pc(s).	9666.730	-	9666.730	-	-	-	9666.730 305
Equipment support connectors	4 pc(s).	9666.740	-	9666.740	-	9666.740	-	9666.740 305

1 WU $\hat{=}$ 250 mm, 1 WU $\hat{=}$ 150 mm

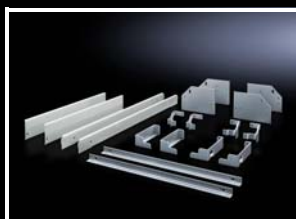

Mounting kits

for AE

For mounting installation modules in AE enclosures.

Note:

- Compact enclosures AE, see from page 47

Supply includes:

- Support plates
- Spacer brackets
- Contact hazard protection
- Angle bracket for contact hazard protection
- Horizontal mounting angle
- Assembly parts

For enclosure	Packs of							Page
Design: Sheet steel, spray finished Model No.		1038.500	1057.500	1076.500	1090.500	1260.500	1213.500	
Design: Stainless steel 1.4301 Model No.		1008.600	-	1012.600	-	-	-	1019.600
Design: Stainless steel 1.4404 Model No.		-	-	-	-	-	-	1019.500
Enclosure width mm		380	500	600	600	600	1000	
Enclosure height mm		600	700	760	1000	1200	1200	
Enclosure depth mm		210	250	210	250	300	300	
Width unit (WU)		1	1	2	2	2	3	
Height unit (U)		3	4	4	6	7	7	
Model No.	1 pc(s).	9666.800	9666.810	9666.820	9666.830	9666.840	9666.850	
Accessories								
Mounting angle 3 U	2 pc(s).	9666.753	-	-	-	-	-	305
Mounting angle 4 U	2 pc(s).	-	9666.754	9666.754	-	-	-	305
Mounting angle 6 U	2 pc(s).	-	-	-	9666.756	-	-	305
Mounting angle 7 U	2 pc(s).	-	-	-	-	9666.757	9666.757	305

1 WU $\hat{=}$ 250 mm, 1 WU $\hat{=}$ 150 mm