

Rack-mounted fans for 482.6 mm (19")



Climate control accessories Page 369

Supply includes:


- Fully wired unit ready for connection
- Terminal strip and assembly parts

Approvals:

Available on the Internet

Technical details:

Available on the Internet

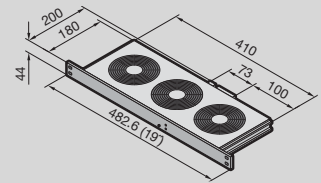

Air throughput 320 – 480 m³/h

Model No.	Packs of	3340.230	3341.115	3341.230	3342.024	3342.230	3342.500	Page
With monitoring		-	-	-	-	-	■	
Rated operating voltage V, ~, Hz		230, 1~, 50/60	115, 1~, 50/60	230, 1~, 50/60	24 (DC)	230, 1~, 50/60	115 - 230, 1~, 50/60 24 (DC)	
Air throughput, unimpeded air flow m³/h		320	480	480	480	480	480	
No. of fans		2	3	3	3	3	3	
Distance between axes mm		85	85	85	105	105	105	
Rated current A		0.24 / 0.22	0.69 / 0.69	0.36 / 0.33	0.74	0.36 / 0.33	0.85	
Pre-fuse A		6	6	6	6	6	6	
Width mm		482.6	482.6	482.6	482.6	482.6	482.6	
Height mm		44	44	44	44	44	44	
Depth mm		200	200	200	200	200	200	
Operating temperature range		-10°C...+55°C	-10°C...+55°C	-10°C...+55°C	-10°C...+55°C	-10°C...+55°C	-10°C...+55°C	
Noise level dB(A)		51	52	51	51	51	51	

Accessories

Digital enclosure internal temperature display and thermostat	1 pc(s).	3114.200	3114.200	3114.200	3114.200	3114.200	3114.200	379
Enclosure internal thermostat	1 pc(s).	3110.000	3110.000	3110.000	3110.000	3110.000	3110.000	379
Speed control	1 pc(s).	3120.200	3120.200	3120.200	-	3120.200	-	381