

Angle bracket PS

For quick attachment of punched rails 23 x 23 mm.

Installation options:

- On the vertical TS enclosure section via
 - Adaptor rail for PS compatibility, see page 997
- On the horizontal TS enclosure section
- On enclosures and rails with rectangular system punching 12.5 x 10.5 mm.

Material:

Sheet steel, zinc-plated, passivated

Supply includes:

- 1 set =
 1 angle bracket, left,
 1 angle bracket, right,
 2 metal screws 5.5 x 13 mm.



Packs of	Model No. PS
12 sets	4181.000



Also required:

U nuts for punched rails (recommended: M6), see page 1010.
 Multi-tooth screws M6 x 12 mm, see page 1011.



Support bracket TS

For the attachment of punched sections without mounting flange 23 x 73 mm or punched rails 23 x 23 mm.

Installation options:


- On the vertical and horizontal TS enclosure section
 - on a 25 mm pitch pattern
 - in 2 mm increments.

Material:

Die-cast zinc

Supply includes:

- 1 set =
 1 support bracket,
 1 stay,
 3 metal screws 5.5 x 13 mm.

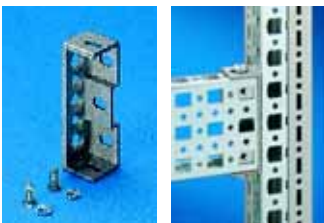

Support bracket PS

For the attachment of punched sections without mounting flange 23 x 73 mm or punched rails 23 x 23 mm.

Installation options:

- On the vertical TS enclosure section via
 - Snap-on nut TS 8800.806, see page 1005, or
 - Adaptor rail for PS compatibility, see page 997
- On the horizontal TS enclosure section
- On enclosures and rails with rectangular system punching 12.5 x 10.5 mm.

Material:

Die-cast zinc

Supply includes:

- 1 set =
 1 support bracket,
 2 countersunk screws,
 2 serrated lock washers.



Packs of	Model No. TS
6 sets	8800.330

German patent no. 199 37 892



Also required:

U nuts for punched rails (recommended: M6), see page 1010.
 Multi-tooth screws M6 x 12 mm, see page 1011.

Packs of	Model No. PS
24 sets	4183.000



Also required:

U nuts for punched rails (recommended: M6), see page 1010.
 Multi-tooth screws M6 x 12 mm, see page 1011.
 Adaptor rail for PS compatibility (when mounting on the vertical enclosure section), see page 997.