

System enclosures SE 8



System accessories Page 507 SE 8 sheet steel Page 81

The system enclosure is based on the TS 8 platform. System accessories for interior installation in the TS 8 design can be used without restrictions.

Material and surface finish:

- Enclosure: Stainless steel 1.4301 (AISI 304), 1.5 mm, exterior brushed, grain size 400
- Door: Stainless steel 1.4301 (AISI 304), 2 mm, exterior brushed, grain size 400
- Rear panel: Stainless steel 1.4301 (AISI 304), 1.5 mm, exterior brushed, grain size 400
- Mounting plate: Sheet steel, 3 mm, zinc-plated
- Gland plates: Stainless steel 1.4301 (AISI 304), 1.5 mm, uncoated

Protection category IP to IEC 60 529:

- IP 55

Protection category NEMA:

- NEMA 12

Supply includes:

- Enclosure, solid top and sides
- Door(s)
- R/h door hinge with single-door enclosures, may be swapped to opposite side
- Rear panel, one-piece, detachable
- Mounting plate
- Gland plates
- Lock: 3 mm double-bit

Note:


- Due to the hardness of the material, we recommend using metal multi-tooth screws for the interior installation.

Approvals:

- UL
- cUL

Technical details:

Available on the Internet

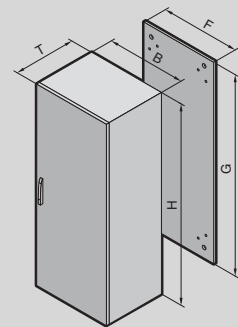

Stainless steel

Width (B) mm	Packs of	600	600	800	800	1000	1200	Page
Height (H) mm		1600	1800	1800	2000	1800	2000	
Depth (T) mm		400	500	500	600	400	500	
Mounting plate width (F) mm		499	499	699	699	899	1099	
Mounting plate height (G) mm		1496	1696	1696	1896	1696	1896	
Model No.	1 pc(s).	5850.500	5851.500	5852.500	5853.500	5854.500	5855.500	
Door(s)		1	1	1	1	1	2	
Weight kg		87.0	99.0	121.0	139.0	133.0	196.0	

Accessories

Base/plinth trim panels, side, 100 mm	1 set(s)	8701.040	8701.050	8701.050	8701.060	8701.040	8701.050	518
Base/plinth components, front and rear, 100 mm	1 set(s)	8701.600	8701.600	8701.800	8701.800	8701.000	8701.200	518
Base/plinth trim panels, side, 200 mm	1 set(s)	8702.040	8702.050	8702.050	8702.060	8702.040	8702.050	518
Base/plinth components, front and rear, 200 mm	1 set(s)	8702.600	8702.600	8702.800	8702.800	8702.000	8702.200	518
Eyebolts	4 pc(s).	4568.500	4568.500	4568.500	4568.500	4568.500	4568.500	586
Rail systems		from page	from page	from page	from page	from page	from page	605
Cable clamp rails	2 pc(s).	4191.000	4191.000	4192.000	4192.000	4336.000	4196.000	665
Levelling feet	4 pc(s).	4612.000	4612.000	4612.000	4612.000	4612.000	4612.000	521
Sheet steel wiring plan pockets	1 pc(s).	4116.000	4116.000	4118.000	4118.000	4124.000	4116.000	578
Metal multi-tooth screws	300 pc(s).	2486.300	2486.300	2486.300	2486.300	2486.300	2486.300	625
System lights		from page	from page	from page	from page	from page	from page	634
Earth straps		see page	see page	see page	see page	see page	see page	644
Snap-on nut TS		see page	see page	see page	see page	see page	see page	618
Cable duct for vertical TS section		see page	see page	see page	see page	see page	see page	663
Door stay		from page	from page	from page	from page	from page	from page	578
Lock systems		from page	from page	from page	from page	from page	from page	563