

### Base/plinth components front and rear

#### Sheet steel for TS, TS-IT, SE, CM, TP, PC, IW

Base/plinth component consisting of one trim panel and two pre-configured corner pieces. In 200 mm high base/plinth components, one trim panel is divided into two for cable entry.

#### Material:

- Base/plinth components: Sheet steel
- Cover caps: Plastic

#### Surface finish:

- Spray-finished

#### Colour:

- Cover caps: RAL 9005/7035

#### Supply includes:

- 1 set =
- 2 base/plinth components, 4 cover caps,
- 4 screws and captive nuts M12 for mounting on the enclosure.



#### Also required:

- Depending on the application/load, side base/plinth trim panels, see page 514




#### Accessories:

- Base mounting plate 2817.000, see page 516

#### Technical details:

Available on the Internet

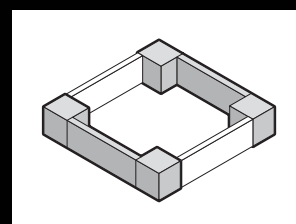

#### 100 mm high, colour: RAL 7022

For enclosure width mm	Version	Model No.
300	Solid	<b>8601.915</b>
400	Solid	<b>8601.400</b>
500	Solid	<b>8601.500</b>
600	Solid	<b>8601.600</b>
800	Solid	<b>8601.800</b>
850	Solid	<b>8601.850</b>
1000	Solid	<b>8601.000</b>
1100	Solid	<b>8601.300</b>
1200	Solid	<b>8601.200</b>
1600	Solid	<b>8601.920</b>
1800	Solid	<b>8601.980</b>

#### 200 mm high, colour: RAL 7022

For enclosure width mm	Version	Model No.
300	Solid	<b>8602.915</b>
400	Solid	<b>8602.400</b>
500	Solid	<b>8602.500</b>
600	Solid	<b>8602.600</b>
800	Solid	<b>8602.800</b>
850	Solid	<b>8602.850</b>
1000	Solid	<b>8602.000</b>
1100	Solid	<b>8602.100</b>
1200	Solid	<b>8602.200</b>
1600	Solid	<b>8602.920</b>
1800	Solid	<b>8602.980</b>

#### 100 mm high, colour: RAL 7035

For enclosure width mm	Version	Model No.
300	Solid	<b>8601.905</b>
600	Solid	<b>8601.605</b>
800	Solid	<b>8601.805</b>

#### 200 mm high, colour: RAL 7035

For enclosure width mm	Version	Model No.
300	Solid	<b>8602.905</b>
600	Solid	<b>8602.605</b>
800	Solid	<b>8602.805</b>