

# Doors/locks

## Viewing panels/operating panels



### Viewing window

#### Stainless steel

Fitted as standard with internal 130° hinges and all-round seal.

The double-bit lock insert may be exchanged for 27 mm lock inserts, type A, and Ergoform-S handle 2452.000.

#### Material:

- Stainless steel 1.4301 (AISI 304)
- Single-pane safety glass

#### Protection category IP to IEC 60 529:

- IP 54


#### Supply includes:

- Assembly parts

Width mm	Height mm	Depth mm	Model No.
522	600	38	<b>2793.560</b>

#### Accessories:

- Lock inserts 27 mm, version A, see page 570
- Ergoform-S handle 2452.000, see page 568

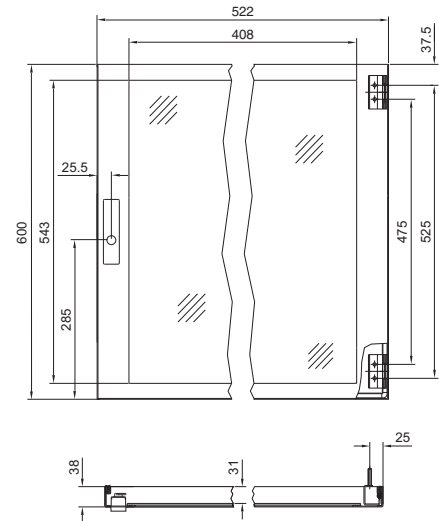

### Monitor frame

#### for door width 600 and 800 mm

For covering a door cut-out, for all standard monitors up to 482.6 mm (19').

#### Protection category IP to IEC 60 529:

- IP 54

#### Supply includes:

- Security glass panel

Dimensions	Width mm	Height mm	Model No.
External dimensions	470	430	<b>2305.000</b>
Viewing area	375	325	
Cut-out required	415	375	

### Identification strips

For individual field identifiers on the door, including transparent cover and assembly parts.

#### For labels:

Width: Enclosure width - 150 mm  
Height: 29 mm  
Thickness: 0.75 mm

#### Colour:

- RAL 7033

For enclosure width mm	Model No.
600	<b>2403.000</b>
800	<b>2404.000</b>